


SW-65・SW-75・SW-85・SW-95・SW-100・SW-120・SW-125・SW-130
 SW-N65・SW-N75・SW-N85・SW-N95・SW-N100・SW-N120・SW-N125・SW-N130
 SW-T75・SW-T95・SW-T100

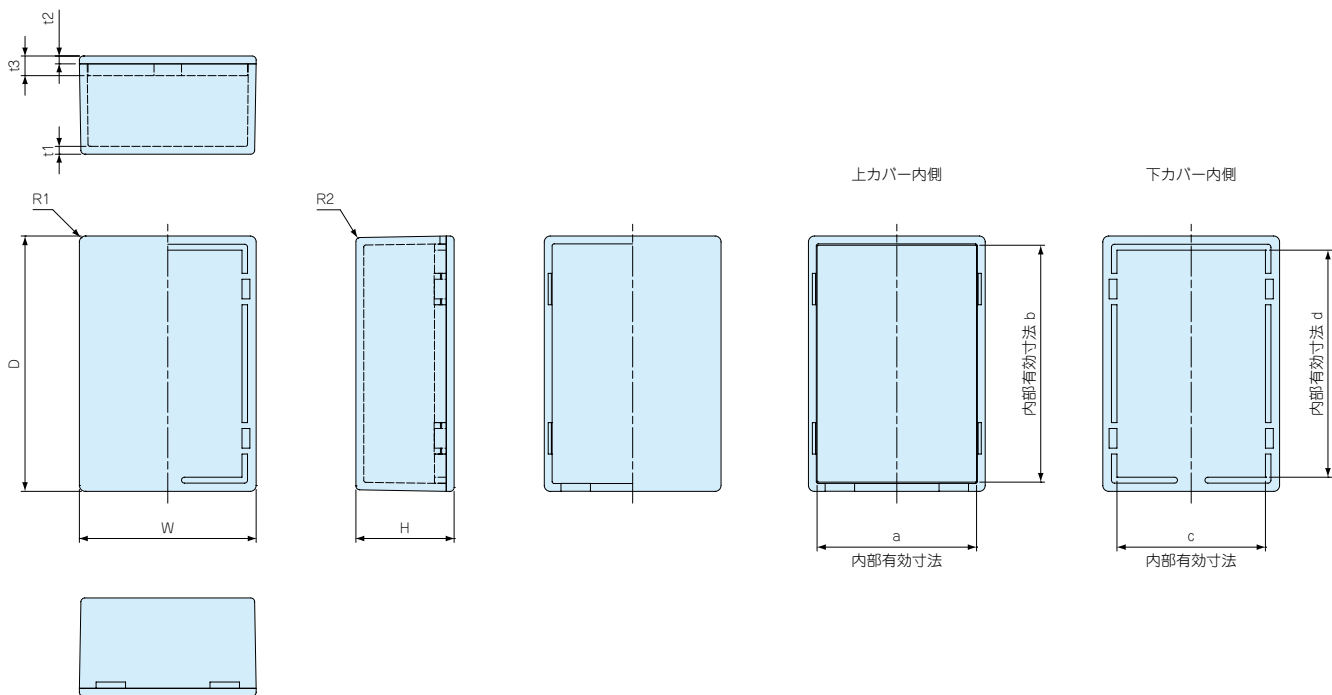

型番	W	H	D	a	b	c	d	t1	t2	t3	R1	R2
SW- 65・SW-N 65	45	25	65	40.6	60.3	37.8	57.8	2	2	5	1.5	1
SW- 75・SW-N 75・SW-T 75	50	30	75	45.2	70.5	42.8	67.8	2	2	5	1.75	0.3
SW- 85・SW-N 85	60	40	85	54.5	79.5	52.8	77.8	2.3	2	5	2	1.5
SW- 95・SW-N 95・SW-T 95	58	18	95	53.7	90.7	50.8	87.8	2	2	5	3	1.5
SW-100・SW-N100・SW-T100	65	35	100	60.6	95.6	57.8	92.8	2	2.5	5.5	2	1.5
SW-120・SW-N120	60	24	120	55.7	115.7	52.8	112.8	2	2.5	5.5	2	1.5
SW-125・SW-N125	70	40	125	65	120	62.8	117.8	2.5	2.5	5.5	3	1.5
SW-130・SW-N130	40	25	130	35.5	125.5	32.8	122.8	2.5	2.5	5.5	3	1.75